

muRata Capacitor Data Sheet

DHRB34A331M2BB


"#" indicates a package specification code.



Last Time Buy Date: 30 Sep 2019 Date of discontinuation: 30 Sep 2020

< List of part numbers with package codes >
DHRB34A331M2BB

Shape

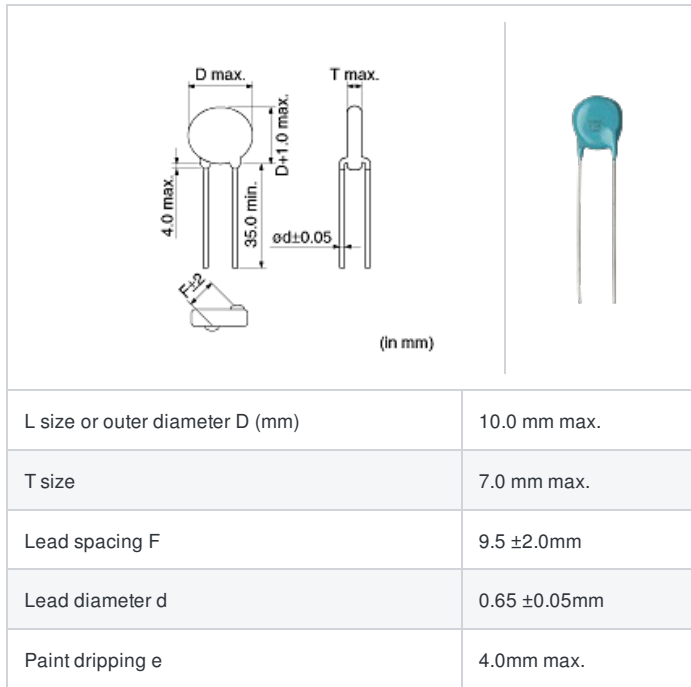

References

Packaging	Specifications	Minimum quantity
B	Packing in bulk	100

Specifications

Capacitance	330pF ±20%
Rated voltage	10kVdc
Temperature characteristics (complied standard)	B(JIS)
Capacitance change rate	±10%
Temperature range of temperature characteristics	-25 to 85°C
Operating temperature range	-25 to 100°C

1 of 1

⚠ Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.